


Handheld Barcode Readers



Which Handheld Should I Choose?

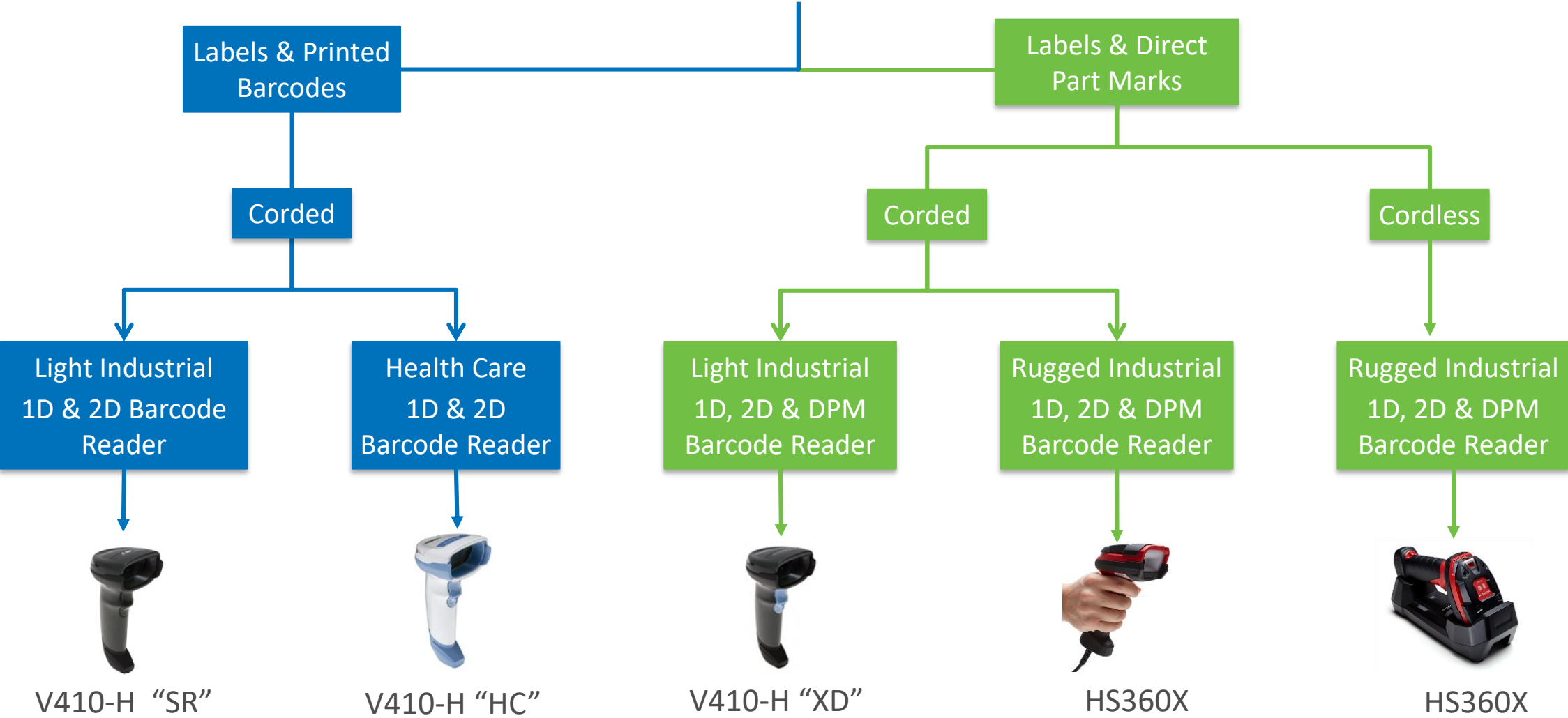

*Click the picture to link to the individual product details

V410-H

Handheld Barcode Readers

[Web Page link](#)



[EtherNet/IP Configuration Guide Link](#)

[Click on pictures to link to datasheet](#)

V410-H Handheld Barcode Readers

- Simple “Point and Shoot” barcode reader for 1D, 2D & Direct Part Marks
- Intended for use in light industrial, manufacturing, laboratory and quality control
- USB and RS232C, Corded connections available
- EtherNet/IP and PROFINET connections available with the optional Network Adapter
- Simple Setup with WeblinkPC Software
- Optional presentation stand available

V410-H
"SR" Model

[Web Page link](#)



V410-H "SR" - Super Range Model

- 1D & 2D Corded Barcode Reader
- Extraordinary Range scanning out to 71cm (28")
- Largest "Sweet-Spot" in the industry for simple point-and-shoot reading
- Eliminates the need to purchase separate readers for close and far range
- Reads virtually any 1D or 2D printed barcode on any medium or digital screen

- Part Number: V410-HDS4608SR

[Click on pictures to link to datasheet](#)

V410-H
“HC” Model

[Web Page link](#)



V410-H “HC” - Health Care Model

- 1D & 2D Corded Barcode Reader
- Read barcodes out to 45cm (18”)
- Safe LED aimer is easy on the eyes
- Special disinfectant-ready plastic housing to help prevent the spread of germs
- ‘Do-not-disturb’ modes for scanner with visual, haptic and audible feedback
- Improve patient safety and increase caregiver productivity with next generation scanning

- Part Number: V410-HDS4608HC

[Click on pictures to link to datasheet](#)

V410-H
"XD" Model

[Web Page link](#)



[Click on pictures to link to datasheet](#)

V410-H "XD" - X Mode, DPM Model

- 1D/2D & DPM Barcode Reader with X-Mode
- Reading from near contact to 21 cm (8") away
- Reading barcodes down to 2mils (element size)
- Capable of reading compact and high density labels or direct part marks, all in the same barcode reader

- Part Number: V410-HDS4608XD

HS360X

[Web Page link](#)

[Configuration Guide Link](#)

[FAQs](#)



HS360X - Ultra-Rugged Handheld Barcode Reader

- 1D/2D & DPM Barcode Reader with X-Mode
- Superior “Ultra-Rugged” Performance
- Corded and Cordless Models
- USB and RS232C, connections available
- EtherNet/IP and PROFINET connections available with the optional Network Adapter
- Simple Setup with WeblinkPC Software
- Optional presentation stand available

[EtherNet/IP Configuration Guide Link](#)

Click on picture to link to [datasheet](#)

HS360X

[Web Page link](#)

[Configuration Guide Link](#)

[FAQs](#)



HS360X Ultra-Rugged Handheld Barcode Reader

- HS360X Corded Model - Part Number: HDS36080001
- HS360X Cordless Model - Part Number: HDS36870001
- For configuration details and available options see guide [link here](#)

[EtherNet/IP Configuration Guide Link](#)

Click on picture to link to [datasheet](#)

Omron Handheld Barcode Readers

Your trusted partner in traceability

