

Sensing for standard and special applications


Cylindrical M18 Series Photoelectric Sensors



- » Simplicity in setup & installation
- » Compact size for increased installation flexibility
- » Robust waterproof housing


One Family for All Applications

Omron's next generation of photoelectric sensors represents one of the largest varieties of dependable and easy-to-use photoelectric sensors on the market. Regardless of your industry or application, Omron offers the right sensor for the job.

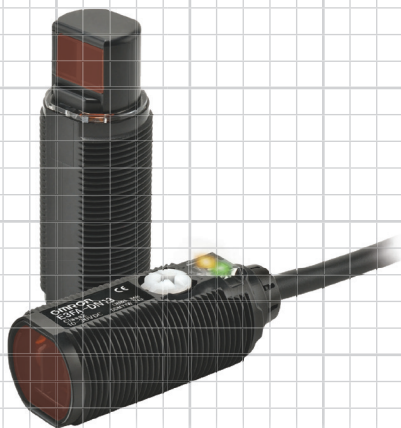


E3FA/E3RA

ABS Plastic Housing

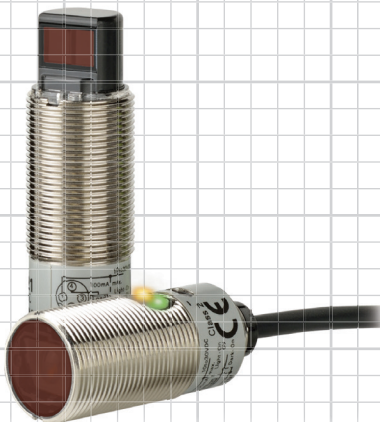

E3FB/E3RB

Nickel-Plated Brass Housing

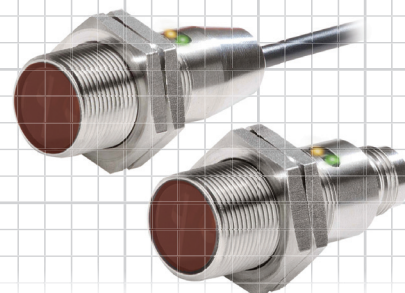

E3FC

Stainless Steel Housing

Key Features

- » Universal M18 cylindrical plastic or nickel-plated brass housing in straight or 90° angled (radial) models
- » SUS316L stainless steel E3FC rated for food grade applications
- » Rugged housing withstands high-pressure and high-temperature wash down
- » High power red LED for easy sensor alignment and dependable outputs in dusty environments
- » All retro reflective models are polarized to prevent false reads on mirrored surfaces
- » High EMC protection and ambient light immunity for detection stability in environments with excess noise or background light
- » Compact size and shape for increased installation flexibility

FIND INFORMATION FAST
Quick Link Shortens Your Search


Quick Link
B278
omron247.com

For complete specifications and additional models and accessories visit **Omron247.com**.


Special Models for Challenging Applications

The cylindrical M18 series includes special models to meet the needs of demanding applications.

- » **Background Suppression** - Provides stable detection of objects of varying color and stable detection without false outputs from objects in the background.
- » **Limited Distance Detection** - Suitable for detecting transparent, shiny, or mirrored film.
- » **Transparent Object Detection** - Retro-reflective sensing with Omron's added P-opaquin function to improve detection of challenging clear targets.
- » **Radial Models** - A full line-up of 90° angled sensing to increase mounting flexibility.
- » **E3FC Series** - A full offering of stainless steel, epoxy-sealed sensors designed for superior environmental and chemical resistance.

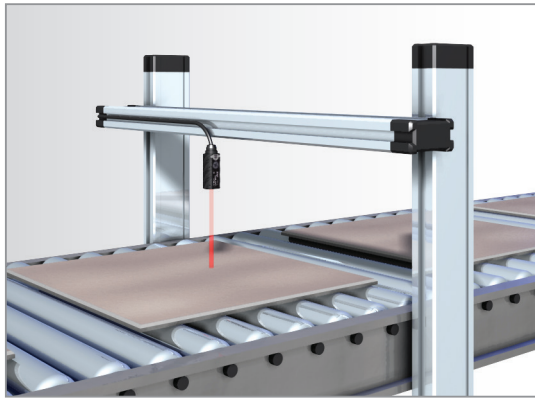

Background suppression sensors for stable detection independent of color or background.

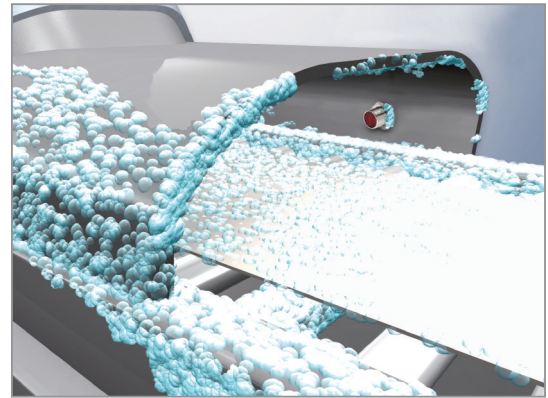

E3FC is best fit for wash-down, detergent applications. Proven with industrial cleaning agents of Ecolab and Diversey.


Unrivalled Detection with Simplicity in Setup and Installation



The short body of the fits in tighter mounting spaces when compared to conventional M18 sensors.




Visible red LED light for easy alignment.

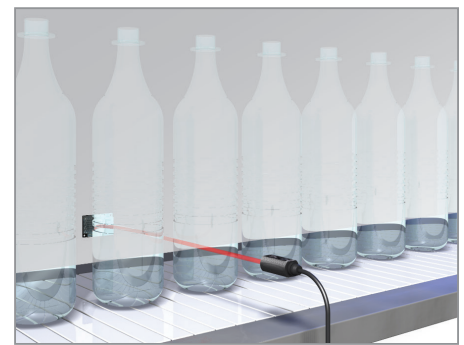

Transparent object detection sensors utilize Omron's unique technology for detecting objects with birefringent (double refraction) properties.



Bright LED indicators for status visibility and large sensor adjusters for use with a standard size screwdriver.

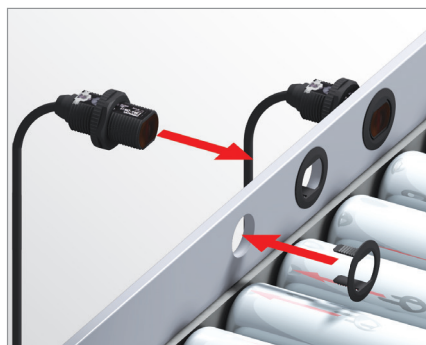

Flush mounting option for quick and easy installation.



High power LED to compensate for dirt and misalignment.

E3FA/E3RA

 
 
 
Plastic Housing Sensors

- » ABS plastic housing for standard applications
- » Compact size with flush mounting option
- » IP67, IP69K for wash down water resistance
- » Straight or Radial models available
- » Background Suppression, Limited Distance, and Transparent Detection models available



Quick Link
B278
omron247.com

Ordering Information

Setup	Sensor type		Sensing distance	PNP		NPN	
				Pre-wired (2m)	M12 connector	Pre-wired (2m)	M12 connector
Straight		Through-beam * 1	20m	E3FA-TP11 2M	E3FA-TP21	E3FA-TN11 2M	E3FA-TN21
		Retro-reflective (using reflector E39-R1S sold separately.)	0.1 to 4m	E3FA-RP11 2M	E3FA-RP21	E3FA-RN11 2M	E3FA-RN21
		Retro-reflective (coaxial) (using reflector E39-R1S sold separately.)	0 to 500mm	E3FA-RP12 2M	E3FA-RP22	E3FA-RN12 2M	E3FA-RN22
		Diffuse-reflective	100mm	E3FA-DP11 2M	E3FA-DP21	E3FA-DN11 2M	E3FA-DN21
			300mm	E3FA-DP12 2M	E3FA-DP22	E3FA-DN12 2M	E3FA-DN22
			1m	E3FA-DP13 2M	E3FA-DP23	E3FA-DN13 2M	E3FA-DN23
	Special Applications		BGS (Background suppression)	100mm	E3FA-LP11 2M	E3FA-LP21	E3FA-LN11 2M
			200mm	E3FA-LP12 2M	E3FA-LP22	E3FA-LN12 2M	E3FA-LN22
		Limited distance reflective	10 to 50mm	E3FA-VP11 2M	E3FA-VP21	E3FA-VN11 2M	E3FA-VN21
		Transparent detection with P-opaquin function (using reflector E39-RP1 sold separately.)	100 to 500mm	E3FA-BP11 2M	E3FA-BP21	E3FA-BN11 2M	E3FA-BN21
			0.1 to 2m	E3FA-BP12 2M	E3FA-BP22	E3FA-BN12 2M	E3FA-BN22
Radial		Through-beam * 1	15m	E3RA-TP11 2M	E3RA-TP21	E3RA-TN11 2M	E3RA-TN21
		Retro-reflective (using reflector E39-R1S sold separately.)	0.1 to 3m	E3RA-RP11 2M	E3RA-RP21	E3RA-RN11 2M	E3RA-RN21
		Diffuse-reflective	100mm	E3RA-DP11 2M	E3RA-DP21	E3RA-DN11 2M	E3RA-DN21
			300mm	E3RA-DP12 2M	E3RA-DP22	E3RA-DN12 2M	E3RA-DN22
			700mm	E3RA-DP13 2M	E3RA-DP23	E3RA-DN13 2M	E3RA-DN23


*1 The set type includes the emitter and receiver.

Note: All sensors are 10-30 VDC. Light-On/Dark-On selectable by wiring.

Note: Please reference the data sheet for infrared emitter options for through-beam and diffuse type E3FA sensors.




E3FB/E3RB Nickel-Plated Brass Housing Sensors

- » Nickel-plated brass housing for applications that require a more ruggedized sensor
- » Compact size with metal flush mounting option
- » IP67, IP69K for wash down water resistance
- » Straight or Radial models available
- » Background Suppression, Limited Distance, and Transparent Detection models available

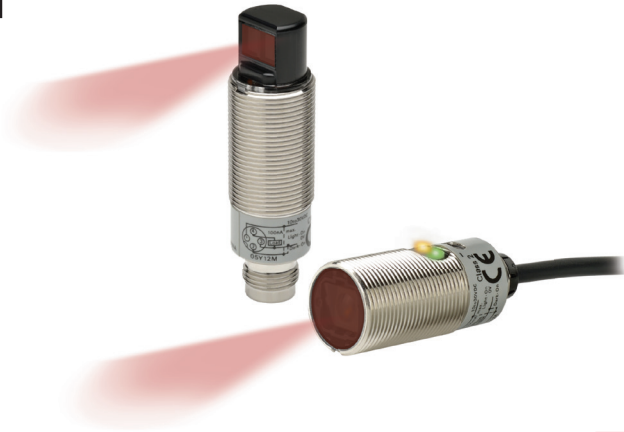

Quick Link
B293
omron247.com

   Ordering Information


Setup	Sensor type		Sensing distance	PNP		NPN	
				Pre-wired (2m)	M12 connector	Pre-wired (2m)	M12 connector
Straight		Through-beam *1	20m	E3FB-TP11 2M	E3FB-TP21	E3FB-TN11 2M	E3FB-TN21
		Retro-reflective (using reflector E39-R1S sold separately.)	0.1 to 4m	E3FB-RP11 2M	E3FB-RP21	E3FB-RN11 2M	E3FB-RN21
		Coaxial Retro-reflective (using reflector E39-R1S sold separately.)	0 to 500mm	E3FB-RP12 2M	E3FB-RP22	E3FB-RN12 2M	E3FB-RN22
		Diffuse-reflective	100mm	E3FB-DP11 2M	E3FB-DP21	E3FB-DN11 2M	E3FB-DN21
			300mm	E3FB-DP12 2M	E3FB-DP22	E3FB-DN12 2M	E3FB-DN22
			1m	E3FB-DP13 2M	E3FB-DP23	E3FB-DN13 2M	E3FB-DN23
	Special Applications		BGS (background suppression)	100mm	E3FB-LP11 2M	E3FB-LP21	E3FB-LN11 2M
			200mm	E3FB-LP12 2M	E3FB-LP22	E3FB-LN12 2M	E3FB-LN22
		Limited distance reflective	10 to 50mm	E3FB-VP11 2M	E3FB-VP21	E3FB-VN11 2M	E3FB-VN21
		Transparent detection with P-opaquist function (using reflector E39-RP1 sold separately.)	100 to 500mm	E3FB-BP11 2M	E3FB-BP21	E3FB-BN11 2M	E3FB-BN21
			0.1 to 2m	E3FB-BP12 2M	E3FB-BP22	E3FB-BN12 2M	E3FB-BN22
Radial		Through-beam	15m	E3RB-TP11 2M	E3RB-TP21	E3RB-TN11 2M	E3RB-TN21
		Retro-reflective (using reflector E39-R1S sold separately.)	0.1 to 3m	E3RB-RP11 2M	E3RB-RP21	E3RB-RN11 2M	E3RB-RN21
		Diffuse reflective	100mm	E3RB-DP11 2M	E3RB-DP21	E3RB-DN11 2M	E3RB-DN21
			300mm	E3RB-DP12 2M	E3RB-DP22	E3RB-DN12 2M	E3RB-DN22
			700mm	E3RB-DP13 2M	E3RB-DP23	E3RB-DN13 2M	E3RB-DN23

*1 The set type includes the emitter and receiver.

Note: All sensors are 10-30 VDC. Light-On/Dark-On selectable by wiring.

E3FC Stainless Steel Metal Housing Sensors

- » High grade stainless steel housing (SUS316L)
- » IP67, IP68, and IP69K to resist high temperature wash down
- » Epoxy resin preventing water ingress if connector is not fixed properly
- » Proven with various industrial detergents of Ecolab and Diversey
- » Background Suppression models available

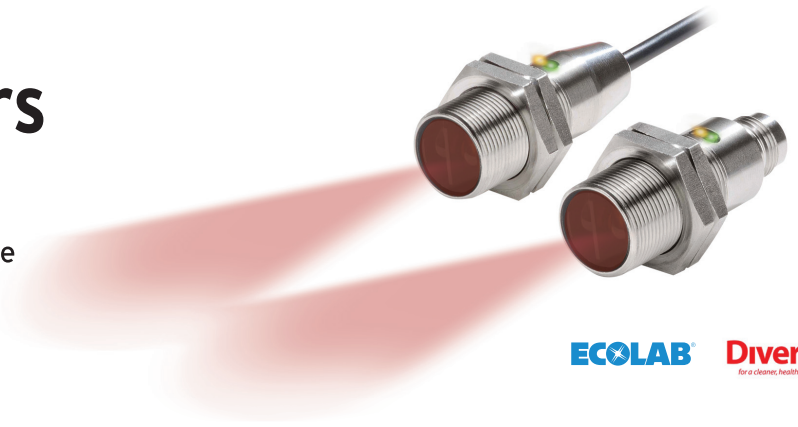

Quick Link
B294
omron247.com

Ordering Information

Sensor type		Sensing distance	PNP		NPN	
			Pre-wired (2m)	M12 connector	Pre-wired (2m)	M12 connector
	Through-beam *1	20m	E3FC-TP11 2M	E3FC-TP21	E3FC-TN11 2M	E3FC-TN21
	Retro-reflective (using reflector E39-R1S sold separately.)	0.1 to 4m	E3FC-RP11 2M	E3FC-RP21	E3FC-RN11 2M	E3FC-RN21
	Diffuse-reflective	300mm	E3FC-DP12 2M	E3FC-DP22	E3FC-DN12 2M	E3FC-DN22
		1m	E3FC-DP13 2M	E3FC-DP23	E3FC-DN13 2M	E3FC-DN23
	BGS (background suppression)	100mm	E3FC-LP11 2M	E3FC-LP21	E3FC-LN11 2M	E3FC-LN21
		200mm	E3FC-LP12 2M	E3FC-LP22	E3FC-LN12 2M	E3FC-LN22

*1 The set type includes the emitter and receiver.


Note: All sensors are 10-30 VDC. Light-On/Dark-On selectable by wiring.

Note: Please reference data sheet for infrared options for diffuse-reflective type E3FC sensors.

Refer to the following when using these agents:

Manufacturer	Product name	Concentration	Test time
	Diverfoam SMS HD	5%	720 h
	Oxofoam	5%	720 h
	Acifoam	5%	720 h
	Divosan Hypochlorite	1%	720 h
	Divosan Forte	1%	720 h
	P3-topactive® 200	5%	720 h
	P3-topax® 56	5%	720 h
	P3-topactive® OKTO	3%	720 h
	P3-topax® 990	3%	720 h
	P3-topax® 66	3%	720 h



E3FC Cylindrical M18

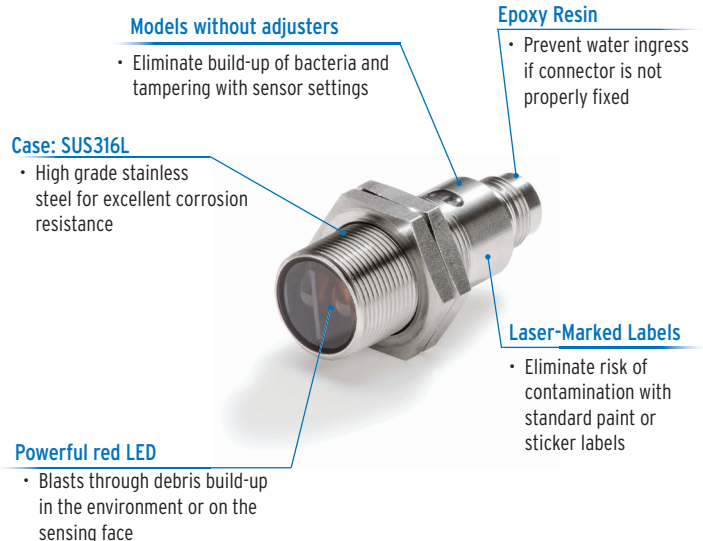

Accessories


Reflectors

  Reflectors required for Retro-reflective Sensors: A Reflector is not provided with the Sensor. Be sure to order a Reflector separately.

Sensor	Sensing distance	Appearance	Model	Quantity	Remarks
E3FA-R□1 E3FB-R□1	0.1 to 4 m		E39-R1S	1	for E3FA-R□, E3RA-R□, for E3FB-R□ and E3RB-R□
E3FA-R□2 E3FB-R□2	0 to 500 mm				
E3FA-B□1 E3FB-B□1	100 to 500 mm		E39-RP1	1	for E3FA-B□ and E3FB-B□
E3FA-B□2 E3FB-B□2	0.1 to 2 m				
E3FC-R□	0.1 to 4 m		E39-R50	1	IP67, IP69K Ecolab tested plastic material

Mounting Brackets

A Mounting Bracket is not included with the Sensor. Order a Mounting Bracket separately if required.

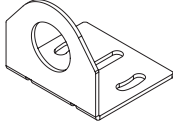Sensor	Appearance	Model (Material)	Quantity	Remarks
All types		E39-L183 (SUS304)	1	Mounting bracket
E3FA-□ E3RA-□		E39-L182 (POM)	1	Flush mounting bracket
E3FB-□ E3FC-□		E39-EL16 (SUS316L)	1	M18 Flush mounting nut

Sensor I/O connectors

Models for Connectors: A Connector is not provided with the Sensor. Be sure to order a Connector separately.

Size	Cable	Appearance	Cable Type		Remarks
M12	Standard	Straight 	2 m	4-wire	XS2F-M12PVC4S2M
			5 m		XS2F-M12PVC4S5M
		Angle 	2 m		XS2F-M12PVC4A2M
			5 m		XS2F-M12PVC4A5M
	Detergent resistant connector cable	Straight 	2 m	4-wire	Y92E-S12PVC4S2M-L
			5 m		Y92E-S12PVC4S5M-L
		Angle 	2 m		Y92E-S12PVC4A2M-L
			5 m		Y92E-S12PVC4A5M-L

OMRON AUTOMATION AND SAFETY • THE AMERICAS HEADQUARTERS • Chicago, IL USA • 847.843.7900 • 800.556.6766 • www.omron247.com

OMRON CANADA, INC. • HEAD OFFICE

Toronto, ON, Canada • 416.286.6465 • 866.986.6766 • www.omron247.com

OMRON ELECTRONICS DE MEXICO • HEAD OFFICE

México DF • 52.55.59.01.43.00 • 01-800-226-6766 • mela@omron.com

OMRON ELECTRONICS DE MEXICO • SALES OFFICE

Apodaca, N.L. • 52.81.11.56.99.20 • 01-800-226-6766 • mela@omron.com

OMRON ELETRÔNICA DO BRASIL LTDA • HEAD OFFICE

São Paulo, SP, Brasil • 55.11.2101.6300 • www.omron.com.br

OMRON ARGENTINA • SALES OFFICE

Cono Sur • 54.11.4783.5300

OMRON CHILE • SALES OFFICE

Santiago • 56.9.9917.3920

OTHER OMRON LATIN AMERICA SALES

54.11.4783.5300

OMRON EUROPE B.V. • Wegalaan 67-69, NL-2132 JD, Hoofddorp, The Netherlands. • +31 (0) 23 568 13 00 • www.industrial.omron.eu

Authorized Distributor:

Automation Control Systems

- Machine Automation Controllers (MAC) • Programmable Controllers (PLC)
- Operator interfaces (HMI) • Distributed I/O • Software

Drives & Motion Controls

- Servo & AC Drives • Motion Controllers & Encoders

Temperature & Process Controllers

- Single and Multi-loop Controllers

Sensors & Vision

- Proximity Sensors • Photoelectric Sensors • Fiber-Optic Sensors
- Amplified Photomicrosensors • Measurement Sensors
- Ultrasonic Sensors • Vision Sensors

Industrial Components

- RFID/Code Readers • Relays • Pushbuttons & Indicators
- Limit and Basic Switches • Timers • Counters • Metering Devices
- Power Supplies

Safety

- Laser Scanners • Safety Mats • Edges and Bumpers • Programmable Safety Controllers • Light Curtains • Safety Relays • Safety Interlock Switches